


962-025-047 BLUMARK RF COAX CABLE, CONNECTOR CONTACT, AND MULTI-PORT HOUSING COMPATIBILITY MATRIX

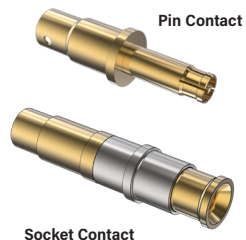


962-025-047

BLUMARK  
COAX CABLES RF

- 50 ohm size 047 (.056" jacket diameter, .011" conductor), 70 GHz maximum bandwidth low-attenuation cable
- -65 to +165 °C rated operating temperature
- FEP jacket, PFA dielectric, solid SPC center conductor
- Double-shielded: Tape/braid shield layers with >90 dB shield effectiveness


Size 12 for use with  
-047 cable  
40 GHz SMPM interface  
50 Ohm  
Solder termination  
Snap-in, rear release  
pin and socket coax  
contacts, spring-loaded.

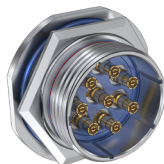

Series 23 SuperNine  
"Better than QPL" MIL-DTL-38999 Series III



Series 806 RF Mil-Aero  
Micro miniature circular IAW D38999

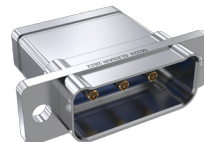

Series 795 RF  
High-performance multi-port rectangular



VITA 67.3 RF  
VPX modular connection system

852-099-03 Pin	✓	✓	✓	
852-154-03 Socket	✓			
852-100-03 Socket		✓	✓	
852-304 (Module, Center Pin)				✓
852-305 (Backplane, Center Socket)				✓