

Selection Guide

SERIES 795

Multi-Port RF Rectangular Connectors

Series 795 connectors accommodate up to nine size 8 BMB-style coax contacts. Contacts snap into connector body and are removable. Environmentally protected with fluorosilicone face seal and rear grommet. One piece connector shell provides a common ground plane and also eliminates EMI radiation through the connector.

Panel mount receptacle has conductive fluorosilicone O-ring for ingress protection. #8-32 jackscrews provide secure mating in high vibration environments.



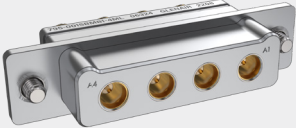
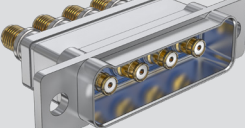
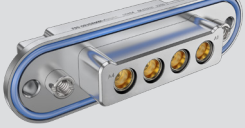
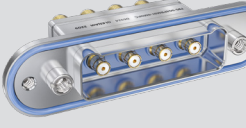
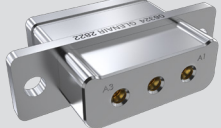
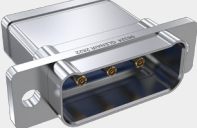

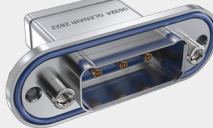

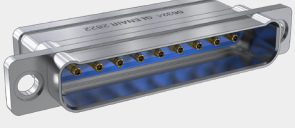
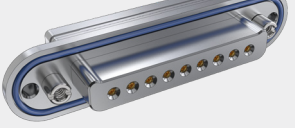
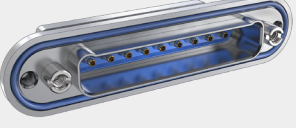
G-Link^{RF} Contacts



18 GHz G-Link^{RF} contacts have a BMB-style mating end and a female SMA interface on the back end. Attach a standard SMA plug cable to the G-Link RF contact.

- Seven layouts for two to nine RF ports (contacts sold separately)
- Rugged one-piece aluminum housing
- Environmental
- Scoop-proof interface
- EMI spring
- BMB-style spring-loaded coax contacts
- Snap-in, rear-release contacts

Series 795 RF Connector Selection Guide

Cable Plugs, Socket Contacts	Cable Receptacles, Pin Contacts	Panel Mount Plugs, Socket Contacts	Panel Mount Receptacles, Pin Contacts
 795-001S (#8 BMB Contacts)	 795-002P (#8 BMB Contacts)	 795-003S (#8 BMB Contacts)	 795-004P (#8 BMB Contacts)
 795-005S (#12 SMPM Contacts)	 795-006P (#12 SMPM Contacts)	 795-007S (#12 SMPM Contacts)	 795-008P (#12 SMPM Contacts)
 795-009S (#16 SMPS Contacts)	 795-010P (#16 SMPS Contacts)	 795-011S (#16 SMPS Contacts)	 795-012P (#16 SMPS Contacts)