

# Conduit Systems for Shipboard Electromagnetic Shielding


## GR2125 Transition Fitting



### TRANSITION FITTING FOR TRIAXIAL CONNECTOR IAW S9407-AB-HBK-010 REV 2, GR2125

How To Order					
<b>Sample Part Number</b>	GR2125	-4	-EM02	-2.5	SN
<b>Basic Part Number</b>	Transition fitting for Triaxial connector				
<b>Dash No.</b>	4, 5, 6, 7. See sales drawing for full dimensional details.				
<b>Conduit Part No.</b>	EM02, EM03, EM04, EM05, EM06, EM08, EM10, EM12, EM16, EM20, EM24				
<b>Body / Adapter Length</b>	In inches. Std. min. length = 2" (one-piece/style A); 2.5" (two-piece/style B)				
<b>Material / Finish</b>	SN = mild steel with cadmium over electroless nickel finish Omit = mild steel with electroless nickel finish IAW AMS 2404C				

GR2000

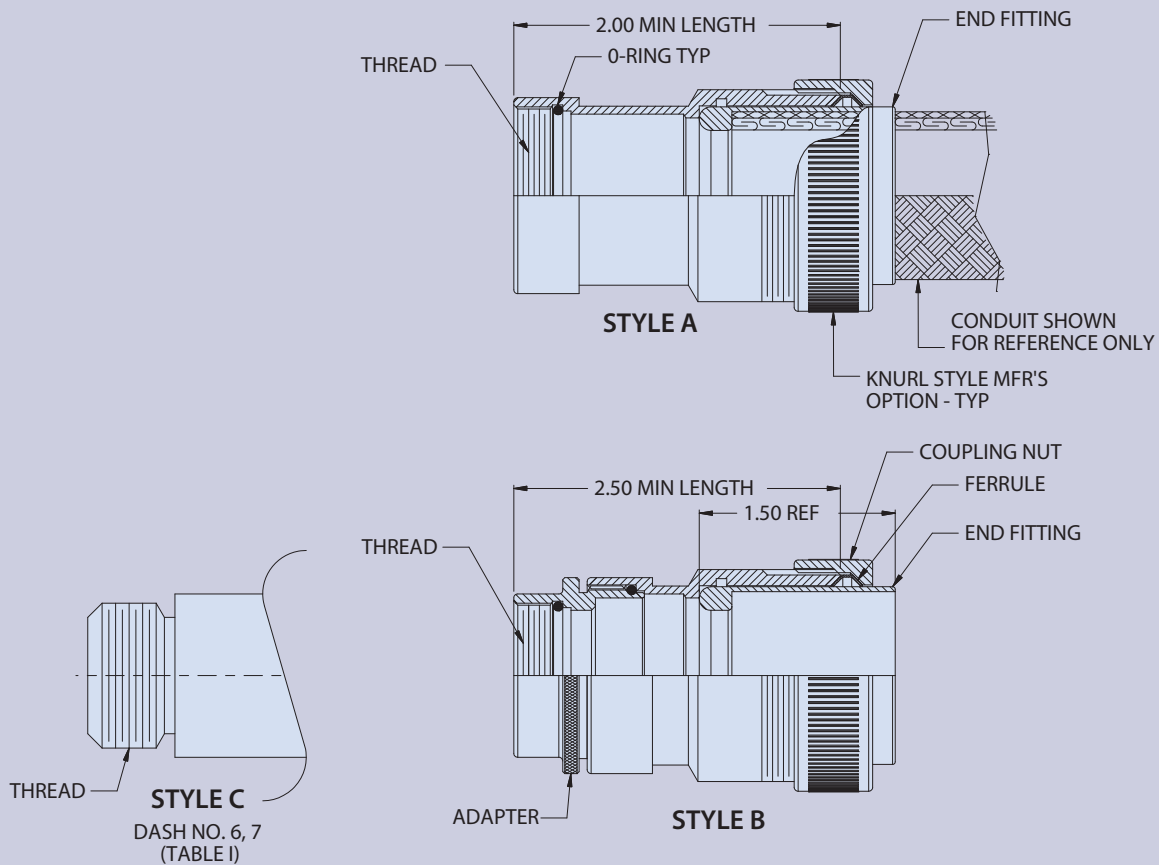

#### MATERIAL / FINISH

Adaper, Body, Ferrule, Nut - Mild Steel AISI Type B1113 IAW Fed-STD-66

End Fitting - 300 Series SST / Passivated

O-Ring - Nitrile/Buna-N